

Technical data sheet

Cover with turn buckle A2

Item number: 6052932



Cover for cable trays and cable ladders with three pairs of turn buckles.
Transverse bead from 500 mm width.
When using covers outdoors, additional measures against the influence of wind must be taken.



VA Stainless steel, grade 354/1

2B Bright, treated

Master data

| | |
|---------------------|------------------------------|
| Item number | 6052932 |
| Type | DRL 400 A2 |
| Description 1 | Cover with turn buckle |
| Description 2 | for cable tray and ladder |
| Manufacturer | OBO |
| Dimension | 400x3000 |
| Material | Stainless steel, grade 354/1 |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 3 |
| Unit of quantity | Metre |
| Weight | 340.4 kg |
| Weight unit | kg/100 m |


Technical data sheet

Cover with turn buckle A2



Item number: 6052932



Dimensions

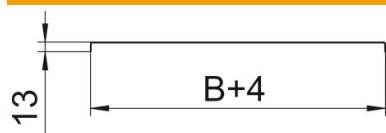

| | |
|------------------|----------|
| Length | 3,000 mm |
| Width | 400 mm |
| Plate thickness | 1 mm |
| Dimension B (mm) | 400 mm |
| Dimension H | 15 mm |

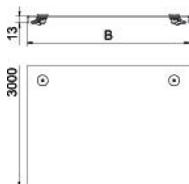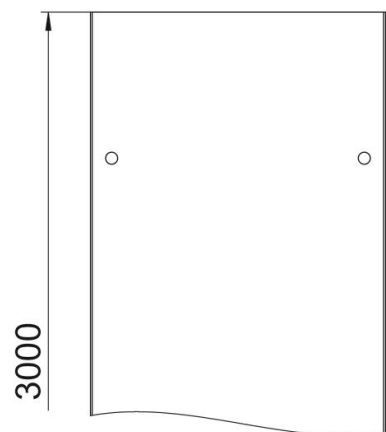

Technical data

| | |
|-------------------------------|-----------|
| Number of turn buckles | 6 St. |
| Fastening type | Sash lock |
| Maintain electrical functions | no |
| Suitable for mesh cable tray | no |
| Suitable for cable ladder | yes |
| Suitable for cable tray | yes |
| Rustproof steel, pickled | no |