

# Technical data sheet

Cable bracket, vertical, for PYROLINE® fire protection ducts, height 60 mm  
Item number: 7215292



Universal cable bracket for the vertical installation of cables in PYROLINE® Con fire protection ducts made of fibreglass-reinforced, lightweight concrete, as well as PYROLINE® Rapid made of sheet steel with an internal coating. The holders are plugged over the head of the loosened fastening screw and then screwed tight to it. The cables can be fastened using cable ties on the lugs or in the slots of the holder. This safely supports the cable weight. Plan at least two cable brackets per metre during installation.

- St** Steel
- FS** Strip galvanized

## Master data


|                     |                              |
|---------------------|------------------------------|
| Item number         | 7215292                      |
| Type                | LHS 60                       |
| Description 1       | Cable fixing device vertical |
| Description 2       | for fire protection duct     |
| Manufacturer        | OBO                          |
| Dimension           | 60x20                        |
| Material            | Steel                        |
| Surface             | Strip galvanized             |
| Surface standard    | DIN EN 10346                 |
| Smallest sales unit | 10                           |
| Unit of quantity    | Piece                        |
| Weight              | 3.507 kg                     |
| Weight unit         | kg/100 pc.                   |

# Technical data sheet

Cable bracket, vertical, for PYROLINE® fire protection ducts, height 60 mm  
Item number: 7215292



## Dimensions

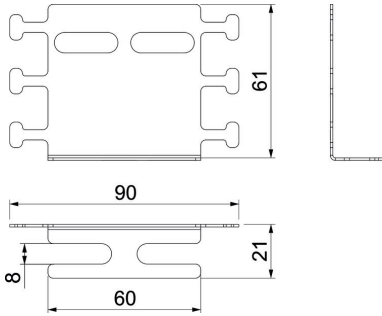

|             |       |
|-------------|-------|
| Length      | 60 mm |
| Width       | 90 mm |
| Height      | 41 mm |
| Dimension B | 21 mm |
| Dimension b | 8 mm  |
| Dimension H | 61 mm |
| Dimension L | 90 mm |
| Dimension I | 60 mm |

## Technical data

|                   |               |
|-------------------|---------------|
| Type of accessory | Miscellaneous |
|-------------------|---------------|