


Technical data sheet

Wiring trunking, type LK4H 40040

Item number: 6132546

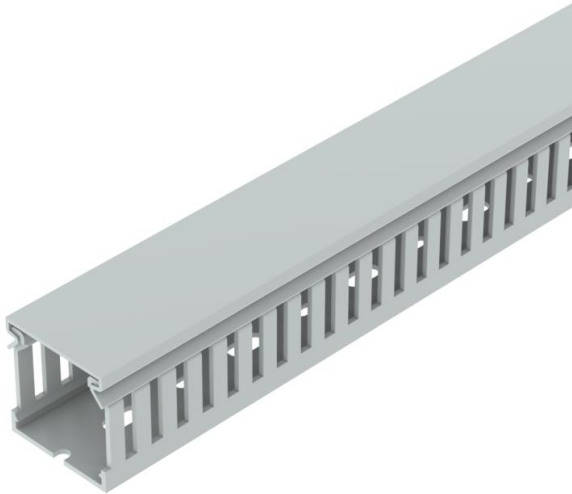

Halogen-free wiring duct, incl. cover and base perforation, for horizontal and vertical routing of electrical cables in the switchgear cabinet. With double-sided adhesive tape on the duct base as a mounting aid. Designed as a metric duct. Retainers are broken out without tools. Special lengths on request. Tested to DIN EN 50085-2-3. Base and cover in set.



PC/ABS Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6132546
Type	LK4H 40040
Description 1	Slotted cable trunking system
Description 2	halogen-free
Manufacturer	OBO
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	2
Unit of quantity	Metre
Weight	50 kg
Weight unit	kg/100 m


Technical data sheet

Wiring trunking, type LK4H 40040

Item number: 6132546



Dimensions

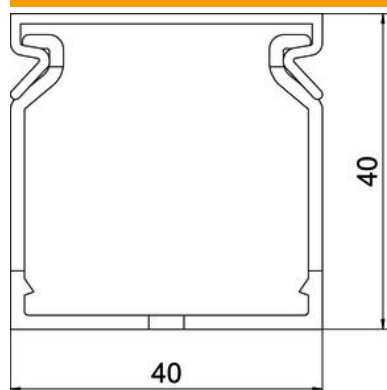

Length	2,000 mm
Width	40 mm
Height	40 mm

Technical data

Side wall version	Slotted
Fastening type	Base perforation
Flexible	no
Halogen-free	yes
Creepage current-resistant	yes
With cover	yes
Usable cross-section	12.33 cm ²
Slot spacing	5.5 mm
Slot width	4.5 mm
Self-extinguishing	yes
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-25 °C