

Technical data sheet

US 7 support A4

Item number: 6341970



U support in fixed lengths. Dimensions 70 x 50 mm.
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 61.



VA Stainless steel, grade 354/1

2B Bright, treated

Technical data sheet

US 7 support A4

Item number: 6341970



Master data

Item number	6341970
Type	US 7 300 A4
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	70x50x3000
Material	Stainless steel, grade 354/1
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	1176.3 kg
Weight unit	kg/100 pc.


Technical data sheet

US 7 support A4


Item number: 6341970



Dimensions

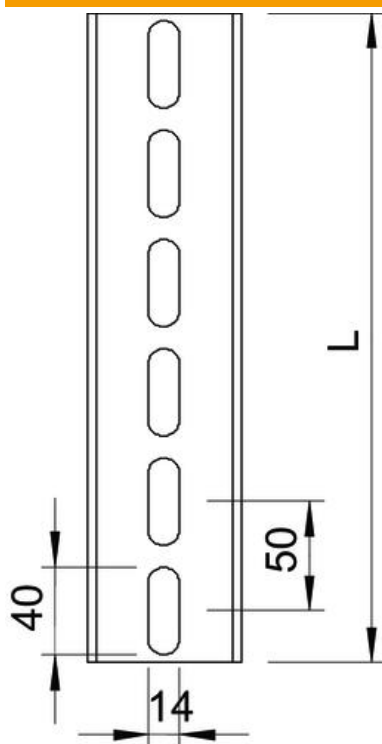

Dimension	70 x 50 x 4
Length	3,000 mm
Width	70 mm
Height	50 mm

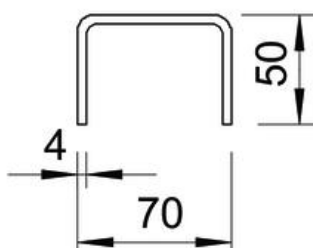

Technical data sheet

US 7 support A4

Item number: 6341970



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
Maintain electrical functions	no
Hole width	14 mm
Material thickness	4 mm
With tothing	no
Profile shape	U profile
Slot width	40 mm
Static value A	4.59 cm ²
Static value Iy	13.79 cm
Static value Iz	36.84 cm
Static value Wy	4.11 cm ²
Static value Wz	10.53 cm ²