



Schlüsselliste Schienen-Systeme

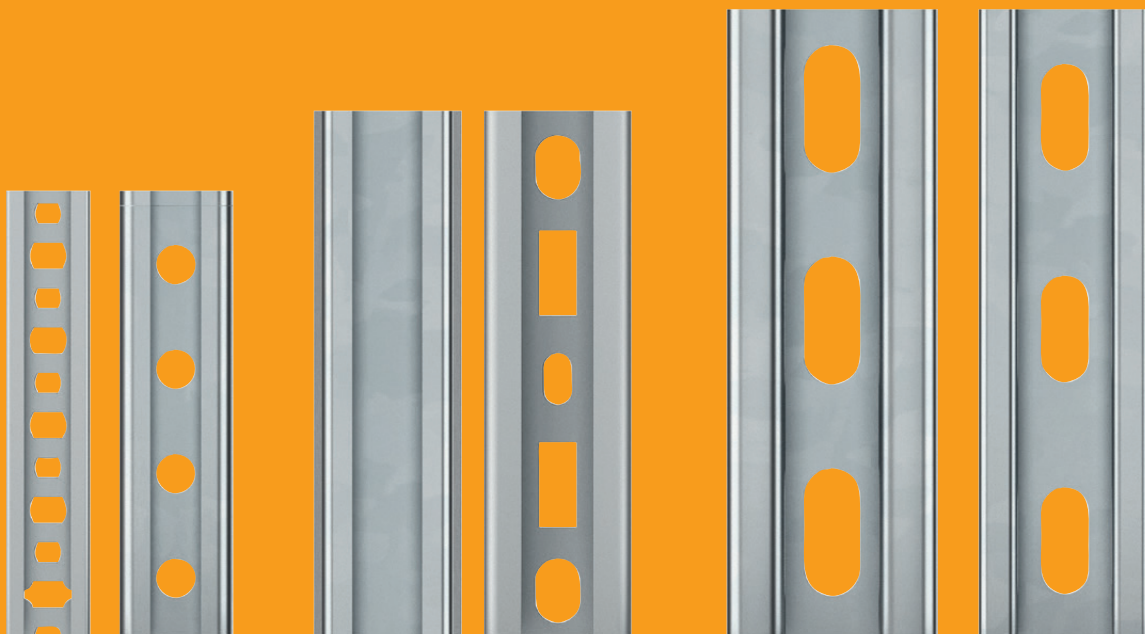

Aufbau der Typen

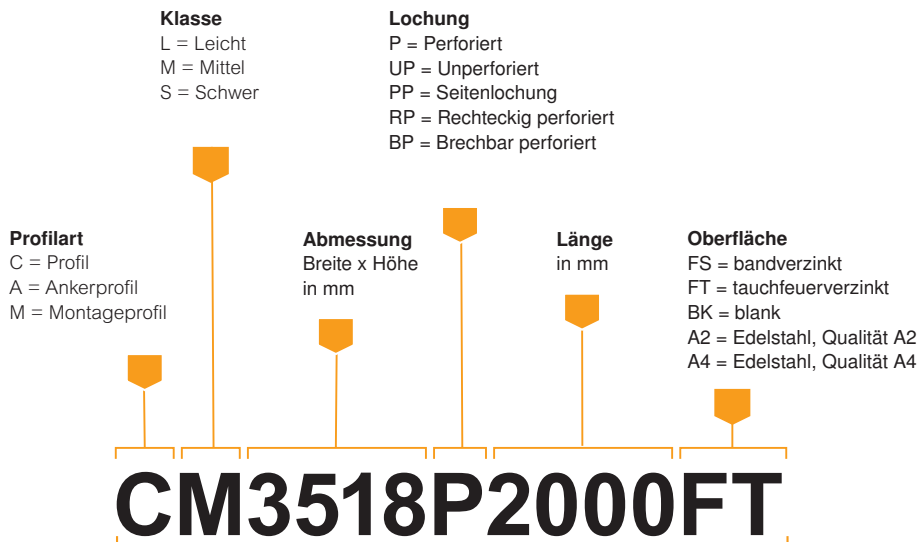

LEICHT

Art.-Nr.	Typ alt	Typ neu	GTIN Artikel
1105124	2060 2M FS	CL2008UP2000FS	4012195039433
1105125	2060 2M VA	CL2008UP2000A2	4012195627098
1106023	2060 2M AB BK	CL2008BP2000BK	4012195039617
1106120	2060 2M AB FS	CL2008BP2000FS	4012195039730
1106627	2060 L 2M FS	CL2008P2000FS	4012195040095
1106628	2060 L 2M VA	CL2008P2000A2	4012195627104
1107127	2061 2M FS	CL2510UP2000FS	4012195040453

Art.-Nr.	Typ alt	Typ neu	GTIN Artikel
1108123	2061 L 2M FS	CL2510P2000FS	4012195040811
1109014	2062 2M BK	CL2712UP2000BK	4012195041412
1109022	2062 2M FT	CL2712UP2000FT	4012195041474
1109529	2062 L 2M FT	CL2712P2000FT	4012195041894
1117033	2066 2M FS	CL2512UP2000FS	4012195046578
1117025	2066 2M FT	CL2512UP2000FT	4012195046516
1117068	2066 2M VA	CL2512UP2000A2	4012195046639

MITTEL

Art.-Nr.	Typ alt	Typ neu	GTIN Artikel
1104284	1268 L 300 FS	CML3518P0300FS	4012195038351
1104292	1268 L 400 FS	CML3518P0400FS	4012195836353
1104306	1268 L 500 FS	CML3518P0500FS	4012195038412
1104310	1268 L 600 FS	CML3518P0600FS	4012195036678
1104315	1268 L 700 FS	CML3518P0700FS	4012195036739
1104320	1268 L 800 FS	CML3518P0800FS	4012195036791
1104325	1268 L 900 FS	CML3518P0900FS	4012195036852
1104497	1268 L 1M FS	CML3518P1000FS	4012195694458
1104500	1268 L 2M FS	CML3518P2000FS	4012195038771
1104498	1268 L 1M VA	CML3518P1000A2	4012195627074
1104501	1268 L 2M VA	CML3518P2000A2	4012195627081
1104349	1268 SL 150 FS	CMS3518P0150FS	4012195038474
1104357	1268 SL 200 FS	CMS3518P0200FS	4012195038535
1104373	1268 SL 300 FS	CMS3518P0300FS	4012195038597
1104391	1268 SL 400 FS	CMS3518P0400FS	4012195052814
1104403	1268 SL 500 FS	CMS3518P0500FS	4012195038658
1104411	1268 SL 600 FS	CMS3518P0600FS	4012195486190
1104427	1268 SL 800 FS	CMS3518P0800FS	4012195051732
1104435	1268 SL 900 FS	CMS3518P0900FS	4012195052630
1104445	1268 SL 1M FS	CMS3518P1000FS	4012195052692
1104454	1268 SL 2M FS	CMS3518P2000FS	4012195038719
1110004	C30 2M FS	CM3015UP2000FS	4012195042075
1110002	C30 L 2M FS	CM3015P2000FS	4012195053897
1109782	C30 L 200 FT	CM3015P0200FT	4012195036975
1109790	C30 L 300 FT	CM3015P0300FT	4012195037033
1109804	C30 L 400 FT	CM3015P0400FT	4012195037095
1109812	C30 L 500 FT	CM3015P0500FT	4012195037156
1109820	C30 L 600 FT	CM3015P0600FT	4012195037217

Art.-Nr.	Typ alt	Typ neu	GTIN Artikel
1109839	C30 L 700 FT	CM3015P0700FT	4012195037279
1109847	C30 L 800 FT	CM3015P0800FT	4012195037330
1109863	C30 L 1M FT	CM3015P1000FT	4012195037934
1109871	C30 L 2M FT	CM3015P2000FT	4012195041771
1118021	2068 2M BK	AML3518UP2000BK	4012195046936
1118226	2068 2M FS	AML3518UP2000FS	4012195047179
1118129	2068 2M FT	AML3518UP2000FT	4012195047056
1119648	2068 L 2M FS	AML3518P2000FS	4012195864318
1119696	2068 L 200 FT	AML3518P0200FT	4012195060673
1119693	2068 L 300 FT	AML3518P0300FT	4012195060611
1119690	2068 L 400 FT	AML3518P0400FT	4012195060376
1119687	2068 L 500 FT	AML3518P0500FT	4012195060253
1119684	2068 L 600 FT	AML3518P0600FT	4012195059417
1119681	2068 L 700 FT	AML3518P0700FT	4012195059356
1119678	2068 L 800 FT	AML3518P0800FT	4012195059295
1119672	2068 L 1M FT	AML3518P1000FT	4012195053958
1119656	2068 L 2M FT	AML3518P2000FT	4012195047599
1119702	2068 L 2M VA	AML3518P2000A2	4012195047650
1119729	2068 L 6M VA	AML3518P6000A2	4012195047711
1112023	2063 2M BK	AMS3518UP2000BK	4012195043157
1112120	2063 2M FS	AMS3518UP2000FS	4012195043270
1112228	2063 2M FT	AMS3518UP2000FT	4012195043393
1110005	2063 2M VA	AMS3518UP2000A2	4012195627111
1112708	2063 L 2M FS	AMS3518P2000FS	4012195632597
1112759	2063 L 2M FT	AMS3518P2000FT	4012195632535
1112709	2063 L 2M VA	AMS3518P2000A2	4012195627128

SCHWER

Art.-Nr.	Typ alt	Typ neu	GTIN Artikel	Art.-Nr.	Typ alt	Typ neu	GTIN Artikel
6007201	CPS 4 SPR 192 FT	MS4022P0192FT	4012196355518	1122947	MS 21 D L 3M FS	MS4142P3000FS	4012195697848
6007228	CPS 4 SPR 292 FT	MS4022P0292FT	4012196005895	1122948	MS 21 D L 6M FS	MS4142P6000FS	4012195697855
6007236	CPS 4 SPR 392 FT	MS4022P0392FT	4012196005956	1122944	MS 21 D L 3M FT	MS4142P3000FT	4012195697794
6007244	CPS 4 SPR 492 FT	MS4022P0492FT	4012196006014	1122945	MS 21 D L 6M FT	MS4142P6000FT	4012195697800
6007252	CPS 4 SPR 592 FT	MS4022P0592FT	4012196006076	1122954	MS 21 D L6M 2V2A	MS4142P6000A2	4012195938019
6007260	CPS 4 SPR 692 FT	MS4022P0692FT	4012196006137				
6007279	CPS 4 SPR 792 FT	MS4022P0792FT	4012196006199	1122970	MS 41 L 1M 2 FS	MSL4141P1000FS	4012195698142
6007287	CPS 4 SPR 892 FT	MS4022P0892FT	4012196006250	1122972	MS 41 L 3M 2 FS	MSL4141P3000FS	4012195698159
6007295	CPS 4 SPR 992 FT	MS4022P0992FT	4012196006311	1122974	MS 41 L 6M 2 FS	MSL4141P6000FS	4012195698166
6007309	CPS 4 SPR1092 FT	MS4022P1092FT	4012196006373	1122962	MS 41 L 1M 2 FT	MSL4141P1000FT	4012195698081
6007317	CPS 4 SPR1192 FT	MS4022P1192FT	4012196006434	1122964	MS 41 L 3M 2 FT	MSL4141P3000FT	4012195698098
6007319	CPS 4 SPR1195 FT	MS4022P1195FT	4012196190379	1122966	MS 41 L 6M 2 FT	MSL4141P6000FT	4012195698104
				1122978	MS 41 L 1M 2 V2A	MSL4141P1000A2	4012195698203
1121979	CPS 4L 2M FT	MS4022P2000FT	4012195050230	1122980	MS 41 L 3M 2 V2A	MSL4141P3000A2	4012195698210
1121898	CPS 4L 6M FT	MS4022P6000FT	4012195049937	1122982	MS 41 L 6M 2 V2A	MSL4141P6000A2	4012195698227
1121960	CPS 4L 2M VA	MS4022P2000A2	4012195050179	1122988	MS 41 L 1M 2 V4A	MSL4141P1000A4	4012195698265
1121901	CPS 4L 6M VA	MS4022P6000A2	4012195049999	1122990	MS 41 L 3M 2 V4A	MSL4141P3000A4	4012195698272
1121963	CPS 4L 2M V4A	MS4022P2000A4	4012195905585	1122992	MS 41 L 6M 2 V4A	MSL4141P6000A4	4012195698289
1121903	CPS 4L 6M V4A	MS4022P6000A4	4012195907022	1123001	MS 41 LS 1M 2 FT	MSL4141PP1000FT	4012195697862
				1123003	MS 41 LS 3M 2 FT	MSL4141PP3000FT	4012195697909
1121391	CPS 5 L 200 FT	MS5030P0200FT	4012195745037	1123005	MS 41 LS 6M 2 FT	MSL4141PP6000FT	4012195697916
1121243	CPS 5 L 300 FT	MS5030P0300FT	4012195672975	1123008	MS 41 LS 1M 2 FS	MSL4141PP1000FS	4012195697923
1121278	CPS 5 L 400 FT	MS5030P0400FT	4012195672555	1123010	MS 41 LS 3M 2 FS	MSL4141PP3000FS	4012195698319
1121405	CPS 5 L 500 FT	MS5030P0500FT	4012195886334	1123012	MS 41 LS 6M 2 FS	MSL4141PP6000FS	4012195698326
1121294	CPS 5 L 600 FT	MS5030P0600FT	4012195672494	1123014	MS 41 LS1M 2 V2A	MSL4141PP1000A2	4012195698333
1121332	CPS 5 L 700 FT	MS5030P0700FT	4012195672616	1123016	MS 41 LS3M 2 V2A	MSL4141PP3000A2	4012195698340
1121308	CPS 5 L 800 FT	MS5030P0800FT	4012195882251	1123018	MS 41 LS6M 2 V2A	MSL4141PP6000A2	4012195698388
1121336	CPS 5 L 900 FT	MS5030P0900FT	4012195068310	1123021	MS 41 LS1M 2 V4A	MSL4141PP1000A4	4012195698395
1121448	CPS 5 L 1M FT	MS5030P1000FT	4012195886211	1123023	MS 41 LS3M 2 V4A	MSL4141PP3000A4	4012195698401
1121363	CPS 5 L 1.5M FT	MS5030P1500FT	4012195514572	1123025	MS 41 LS6M 2 V4A	MSL4141PP6000A4	4012195698432
1121464	CPS 5 L 2M FT	MS5030P2000FT	4012195049210	1122908	MS 41 L 1M FS	MS4141P1000FS	4012195697503
1121466	CPS 5 L 3M FT	MS5030P3000FT	4012195419686	1122910	MS 41 L 3M FS	MS4141P3000FS	4012195686224
1121472	CPS 5 L 6M FT	MS5030P6000FT	4012195462491	1122912	MS 41 L 6M FS	MS4141P6000FS	4012195686231
1121480	CPS 5 L 2M VA	MS5030P2000A2	4012195049272	1122509	MS 41 L 200 FT	MS4141P0200FT	4012195484516
1121499	CPS 5 L 6M VA	MS5030P6000A2	4012195049333	1122517	MS 41 L 300 FT	MS4141P0300FT	4012195485896
1121393	CPS 5 L 200 V4A	MS5030P0200A4	4012195906971	1122525	MS 41 L 400 FT	MS4141P0400FT	4012195486251
1121280	CPS 5 L 400 V4A	MS5030P0400A4	4012195906919	1122533	MS 41 L 500 FT	MS4141P0500FT	4012195486794
1121465	CPS 5 L 2M V4A	MS5030P2000A4	4012195906995	1122541	MS 41 L 600 FT	MS4141P0600FT	4012195486916
1121469	CPS 5 L 3M V4A	MS5030P3000A4	4012195907008	1122568	MS 41 L 700 FT	MS4141P0700FT	4012195487036
1121473	CPS 5 L 6M V4A	MS5030P6000A4	4012195907015	1122576	MS 41 L 800 FT	MS4141P0800FT	4012195487098
6349404	CPS 5 G 220 FT	MS5030RP0220FT	4012196191710	1122584	MS 41 L 900 FT	MS4141P0900FT	4012195487159
6349412	CPS 5 G 260 FT	MS5030RP0260FT	4012196191772	1122606	MS 41 L 1M FT	MS4141P1000FT	4012195487272
6349439	CPS 5 G 300 FT	MS5030RP0300FT	4012196191833	1122622	MS 41 L 3M FT	MS4141P3000FT	4012195487876
6349447	CPS 5 G 340 FT	MS5030RP0340FT	4012196191895	1122657	MS 41 L 6M FT	MS4141P6000FT	4012195488170
6349463	CPS 5 G 380 FT	MS5030RP0380FT	4012196191956	1123033	MS 41 L 300 V4A	MS4141P0300A4	4012195907138
				1123035	MS 41 L 400 V4A	MS4141P0400A4	4012195907145
1122957	MS 21 L 800 FS	MS4121P0800FS	4012195848042	1123039	MS 41 L 600 V4A	MS4141P0600A4	4012195907169
1122918	MS 21 L 2M FS	MS4121P2000FS	4012195686262	1123049	MS 41 L 3M V4A	MS4141P3000A4	4012195907213
1122920	MS 21 L 3M FS	MS4121P3000FS	4012195686279	1123051	MS 41 L 6M V4A	MS4141P6000A4	4012195907220
1122922	MS 21 L 6M FS	MS4121P6000FS	4012195686286	1122481	MS 41 LS 1M FS	MS4141PP1000FS	4012195697978
1122933	MS 21 L 200 FT	MS4121P0200FT	4012195697626	1122914	MS 41 LS 3M FS	MS4141PP3000FS	4012195686248
1122934	MS 21 L 300 FT	MS4121P0300FT	4012195697664	1122916	MS 41 LS 6M FS	MS4141PP6000FS	4012195686255
1122935	MS 21 L 400 FT	MS4121P0400FT	4012195697671	1122500	MS 41 LS 300 FT	MS4141PP0300FT	4012195356325
1122936	MS 21 L 500 FT	MS4121P0500FT	4012195697688	1122501	MS 41 LS 400 FT	MS4141PP0400FT	4012195356332
1122937	MS 21 L 600 FT	MS4121P0600FT	4012195697725	1122479	MS 41 LS 1M FT	MS4141PP1000FT	4012195697961
1122938	MS 21 L 700 FT	MS4121P0700FT	4012195697732	1122483	MS 41 LS 3M FT	MS4141PP3000FT	4012195050735
1122939	MS 21 L 800 FT	MS4121P0800FT	4012195697749	1122487	MS 41 LS 6M FT	MS4141PP6000FT	4012195050742
1122940	MS 21 L 900 FT	MS4121P0900FT	4012195697787	1123079	MS 41 LS 6M V4A	MS4141PP6000A4	4012195907244
1122923	MS 21 L 2M FT	MS4121P2000FT	4012195697541				
1122924	MS 21 L 3M FT	MS4121P3000FT	4012195686293	1122676	MS 41D L 3M 2 FS	MS4182P3000FS	4012195698036
1122926	MS 21 L 6M FT	MS4121P6000FT	4012195686309	1122678	MS 41D L 6M 2 FS	MS4182P6000FS	4012195698043
1122928	MS 21 L 3M V2A	MS4121P3000A2	4012195697558	1122671	MS 41D L 3M 2 FT	MS4182P3000FT	4012195697985
1122929	MS 21 L 6M V2A	MS4121P6000A2	4012195697565	1122673	MS 41D L 6M 2 FT	MS4182P6000FT	4012195698029
1122476	MS 21 L 2M V4A	MS4121P2000A4	4012195907114	1122682	MS 41 D L3M 2V2A	MS4182P3000A2	4012195938026
1122931	MS 21 L 3M V4A	MS4121P3000A4	4012195697602	1122684	MS 41 D L6M 2V2A	MS4182P6000A2	4012195938033
1122932	MS 21 L 6M V4A	MS4121P6000A4	4012195697619				

OBO Bettermann Vertrieb Deutschland GmbH & Co. KG
Langer Brauck 25
58640 Iserlohn
DEUTSCHLAND

Kundenservice Deutschland
Tel.: +49 23 71 78 99-20 00
Fax: +49 23 71 78 99-25 00
info@obo.de
www.obo.de

Building Connections

